



Grooved pin, half length taper grooved DIN 1472 Free-cutting steel 5X30MM

Article number	39720.050.030
Brand	-
UBB	950359136567
UNSPSC	31163215
EAN	8715492825421
PKG. of 100	Full Box Only

Technical Parameters

Diameter	5 mm
Length	30 mm
Material	Free-cutting steel
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

DIN	1472
ISO	≈8745
NEN	≈2603

Technical Specification

c ≈	0.6
d1	5
d2 ≈	5.3
D (mm)	5
L (mm)	30

Technical Drawing

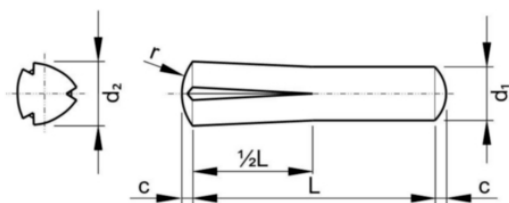

$r \approx$

5

Tolerance

h11

V

16.5