


Hexalobular countersunk
head screw DIN ≈965 A
Stainless steel A2 M2X5

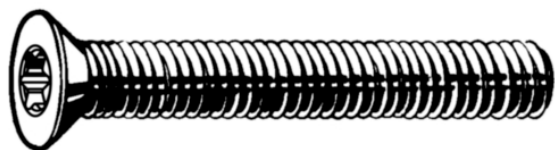

Article number	51305.020.005
Brand	-
UBB	500512300897
UNSPSC	31161504
EAN	8715494275330
PKG. of 1000	Full Box Only

Technical Parameters

Diameter	M2
Length	5 mm
Class	70
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A2
Thread	Metric thread

Standards

DIN	≈965
NF	≈E25-119-1
ISO	≈14581

Technical Specification

d-D	M2
Thread length (min.)	15
dk (max.)	3.8
Full thread if $L \leq$	16
k (max.)	1.2
L (mm)	5
P	0.4
Socket	6

Technical Drawing

