



Grooved pin, half length taper grooved DIN 1472 Stainless steel A1 2X5MM

Article number	51586.020.005
Brand	-
UBB	500696088136
UNSPSC	31163215
EAN	8715492049650
PKG. of 500	Full Box Only

Technical Parameters

Length	5 mm
Material	Stainless steel
Material technical	A1
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

DIN	1472
NEN	≈2603
ISO	≈8745

Technical Specification

c ≈	0.25
d1	2
d2 ≈	2.15
L (mm)	5
r ≈	2

Technical Drawing

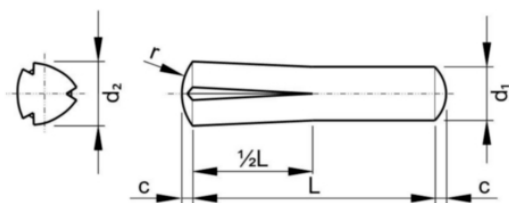

Tolerance

h9

V

2.85