


Hexagon socket set screw with nylon dog point (thrust screw) Steel Plain 5.8 M5X9

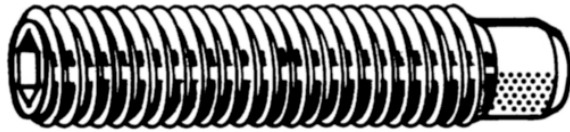

Article number	56949.050.009
Brand	-
UBB	955351312215
UNSPSC	31161518
EAN	8715493750982
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M5
Length	9 mm
Class	5.8
Driving features	Hexagon socket
Material	Steel
Thread direction	Right
Point	Nylon dog
Surface treatment	Plain
Thread	Metric thread

Info

These set screws are designed for pressure loads and are not suitable for tensile- or shear loads. These set screws (thrust screws) are ideal for clamping or exerting pressure on threaded spindles, axles, shafts and coated surfaces without causing damage to the clamped material.

Standards

Technical Specification

d-D	M5
-----	----

Technical Drawing

d2	3
L (mm)	9
P	0.8
s	2.5

