



KIPP Clamping levers, internal thread Chrome Die cast zinc/steel 5.8 High gloss chromed/black oxide M8X65

Article number	58047.080.065
Brand	-
UBB	500689573516
UNSPSC	31162807
EAN	4059245085088
PKG. of 5	Full Box Only

Technical Parameters


Class	5.8
Color	Chrome
D1_MM	18.5mm
Material	Die cast zinc/steel
Surface treatment	High gloss chromed/ black oxide
Thread	Metric thread
Info	Material: Handle die- cast zinc EN 12844. Steel parts grade 5.8.Version: Handle high-gloss chromed. Steel parts black oxidized.

Standards

Technical Specification

A	65
A1	74.5
B	9.5
D	13.5
D1	18.5
D2	19
H	28.5
H2	17.5

Technical Drawing

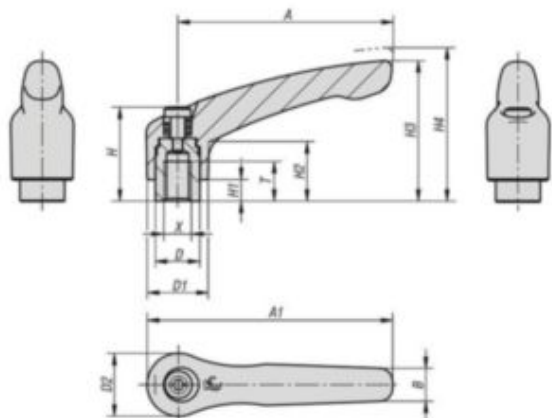

H3	42.5
H4	45.5
H1	6.5
Number of teeth	20
T	12
X	8

FABORY