



Spring plungers with slot and ball, LONG-LOK secured strong spring force Stainless steel 1.4305 M8

Article number	58531.080.001
Brand	-
UBB	500689811460
UNSPSC	31162807
EAN	
PKG. of 10	Full Box Only

Technical Parameters


D1_MM	5mm
Driving features	Slotted
Material	Stainless steel
Material technical	1.4305
Thread	Metric thread
Info	Material: Sleeve 1.4305. Ball 1.4034. Spring 1.4310. LONG-LOK thread lock in nylon.Version: Bright. Ball hardened. L2 = approx. 2x thread pitch.

Standards

Technical Specification

D	8
D1	5
F1 = springiness beginning in N	47
F2 = springiness end in N	73
H	1.5
L1	8
Loosening torque approx. (Nm)	0.37

Technical Drawing

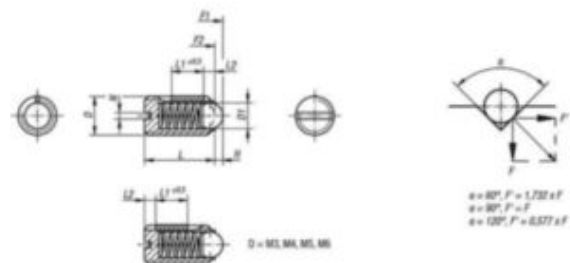

N	1.2
---	-----

L	16
---	----

Tightening torque approx. (Nm)	1.09
-----------------------------------	------