



## Spring plungers with slot and ball, LONG-LOK secured strong spring force Stainless steel 1.4305 M8

Article number 58531.080.001

Brand -

UBB 500689811460

UNSPSC 31162807

EAN

PKG. of 10 Full Box Only

### Technical Parameters


D1_MM	5mm
Driving features	Slotted
Material	Stainless steel
Material technical	1.4305
Thread	Metric thread
Info	Material: Sleeve 1.4305. Ball 1.4034. Spring 1.4310. LONG-LOK thread lock in nylon. Version: Bright. Ball hardened. L2 = approx. 2x thread pitch.

### Standards

### Technical Specification

D	8
D1	5
F1 = springiness beginning in N	47
F2 = springiness end in N	73
H	1.5
L1	8
Loosening torque approx. (Nm)	0.37

### Technical Drawing

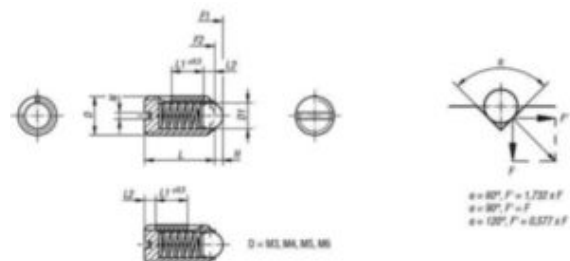

N 1.2

L 16

Tightening torque  
approx. (Nm) 1.09