



## Spring plungers with hexagon socket and ball, LONG-LOK secured standard spring force Steel 5.8 Black oxide M16

Article number 58538.160.001

Brand -

UBB 500689840741

UNSPSC 31162807

EAN

PKG. of 5 Full Box Only

### Technical Parameters


Class	5.8
D1_MM	10mm
Driving features	Hexagon socket
Material	Steel
Surface treatment	Black Oxide
Thread	Metric thread
Info	Material: Sleeve steel grade 5.8. Ball steel. Spring steel grade D. LONG-LOK thread lock nylon. Version: Black oxidized. Ball hardened. L2 = approx. 2x thread pitch.

### Standards

### Technical Specification

D	16
D1	10
F1 = springiness beginning in N	65
F2 = springiness end in N	125
H	3.5

### Technical Drawing

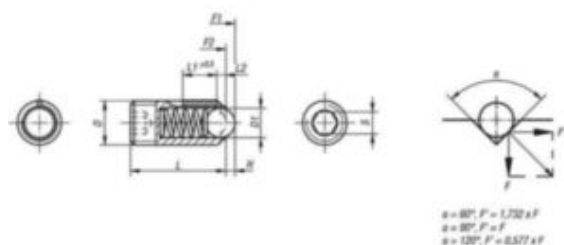

L1	14
Loosening torque approx. (Nm)	3
L	33
S	8
Tightening torque approx. (Nm)	3.9