


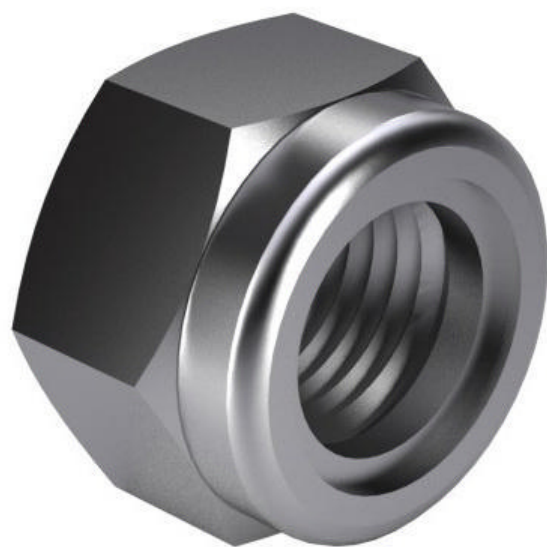

**Prevailing torque type  
hexagon nut with non-  
metallic insert, style NM/NE,  
UNC ASME B18.16.6 Steel  
ASME B18.16.6 Zinc plated  
Gr.N5 7/16-14**

|                |                 |
|----------------|-----------------|
| Article number | U12348.043.0001 |
| Brand          | -               |
| UBB            | 500621429926    |
| UNSPSC         | 31161727        |
| EAN            | 8717077381544   |
| PKG. of 25     | Full Box Only   |

**Technical Parameters**

|                    |                                                                                                         |
|--------------------|---------------------------------------------------------------------------------------------------------|
| Diameter           | 7/16 Inch                                                                                               |
| Class              | Gr.N5                                                                                                   |
| Driving features   | Hexagon                                                                                                 |
| Material           | Steel                                                                                                   |
| Material technical | ASME B18.16.6                                                                                           |
| Thread direction   | Right                                                                                                   |
| Surface treatment  | Zinc plated                                                                                             |
| Thread             | Unified National<br>Coarse                                                                              |
| Threads per inch   | 14                                                                                                      |
| Info               | Number thread<br>diameters (#) are<br>style NM lock nuts,<br>other diameters are<br>style NE lock nuts. |

**Standards**

|      |          |
|------|----------|
| ASME | B18.16.6 |
|------|----------|

**Technical Specification**

|   |       |
|---|-------|
| A | 0.627 |
| C | 0.468 |

**Technical Drawing**

FABORY

