


Espárrago con 2 tuercas hexagonales ASME B16.5/ B18.2.2 Acero ASTM A193 - ASTM A194 Sin revestimiento Gr.B7 - Gr.2H 1/2X105 (4.1/8)

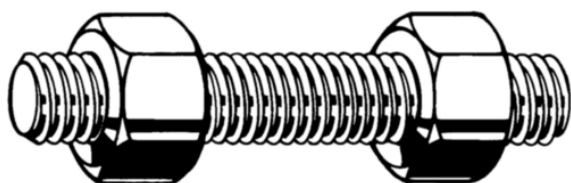

Artículo No.	22080.127.105
Marca	-
UBB	500578014531
UNSPSC	31161619
EAN	8715494332521
Env. de 1	Solo embalaje completo

Parámetros técnicos

Diámetro	1/2
Anchura (L) (mm)	105
Largura (L) (Inch - ft)	4.1/8

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Clase	Gr.B7 - Gr.2H
Material (largo)	Acero
Material técnico	ASTM A193 - ASTM A194
Dirección del hilo	Derecha
Tratamiento de superficie	Sin revestimiento
Rosca (larga)	Unified National Coarse

Normas

ASME	B16.5/B18.2.2
BS	≈4882
ASTM	A193/A194

Especificación técnica

B	7/8
M	12.3
Hilos por pulgada	13

Diseño técnico

