


## Espárrago con 2 tuercas hexagonales ASME B16.5/ B18.2.2 Acero ASTM A193 - ASTM A194 Sin revestimiento Gr.B7 - Gr.2H 5/8X370 (14.1/2)

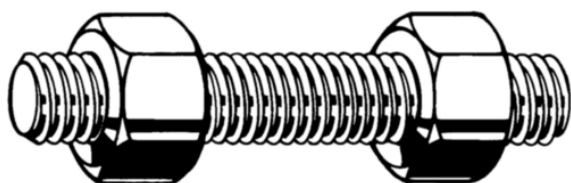

Artículo No.	22080.158.368
Marca	-
UBB	500578018425
UNSPSC	31161619
EAN	8715494337885
Env. de 1	Solo embalaje completo

### Parámetros técnicos

Diámetro	5/8
Anchura (L) (mm)	370
Largura (L) (Inch - ft)	14.1/2

#### Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Clase	Gr.B7 - Gr.2H
Material (largo)	Acero
Material técnico	ASTM A193 - ASTM A194
Dirección del hilo	Derecha
Tratamiento de superficie	Sin revestimiento
Rosca (larga)	Unified National Coarse

### Normas

ASTM	A193/A194
ASME	B16.5/B18.2.2
BS	≈4882

## Especificación técnica

B	1.1/16
M	15.5
Hilos por pulgada	11

## Diseño técnico

