


Espárrago con 2 tuercas hexagonales ASME B16.5/ B18.2.2 Acero ASTM A193 - ASTM A194 Sin revestimiento Gr.B7 - Gr.2H 1 Inch X305 (12)

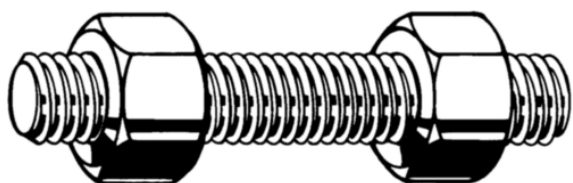

| | |
|--------------|------------------------|
| Artículo No. | 22080.254.304 |
| Marca | - |
| UBB | 950353070994 |
| UNSPSC | 31161619 |
| EAN | 8715492618306 |
| Env. de 1 | Solo embalaje completo |

Parámetros técnicos

| | |
|-------------------------|---------|
| Diámetro | 1 Inch |
| Anchura (L) (mm) | 305 |
| Largura (L) (Inch - ft) | 12 Inch |

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

| | |
|---------------------------|-------------------------|
| Clase | Gr.B7 - Gr.2H |
| Material (largo) | Acero |
| Material técnico | ASTM A193 - ASTM A194 |
| Dirección del hilo | Derecha |
| Tratamiento de superficie | Sin revestimiento |
| Rosca (larga) | Unified National Coarse |

Normas

| | |
|------|---------------|
| BS | ≈4882 |
| ASTM | A193/A194 |
| ASME | B16.5/B18.2.2 |

Especificación técnica

| | |
|-------------------|-------|
| B | 1.5/8 |
| M | 25 |
| Hilos por pulgada | 8 |

Diseño técnico

