


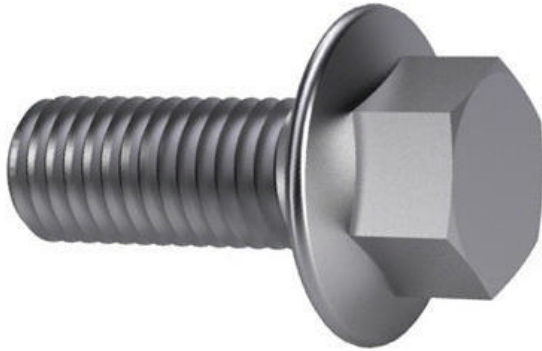

Vis à tête hexagonale à embase DIN 6921 Acier Electro zingué 10.9 M6X20

Numéro d'article	04137.060.020
Marque	-
UBB	500648943503
UNSPSC	31161620
EAN	8717077238480
PKG. de 500	Boîte complete uniquement

Paramètres techniques

Diamètre	M6
Longueur	20 mm
Classe	10.9
Mode d'entraînement	Hexagonale
Forme de tête	Tête hexagonale
Matière	Acier
Direction du filetage	Droit
Revêtement	Electro zingué
Filetage	Filetage métrique

Info

Avertissement:
la galvanisation
électrolytique de
ces produits peut
provoquer un risque
de fragilisation par
l'hydrogène. Specific
features of hexagon
bolts with flange: The
flange enables built
up forces under
the bolt head to be
spread over a larger
area, consequently
resulting in
lower surface
pressure. Large
(oversized) holes
and/or tooling holes

Normes

DIN	6921
EN	≈1665
ISO	≈4162
ASME	≈B18.2.3.4M

FABORY can be covered by
the flange. Washers
are not necessary.

Spécifications techniques

b (min.)	18
d-D	M6
dc (max.)	14.2
k (max.)	6.6
L (mm)	20
P	1
s	10

Dessin technique

