



Hexagon socket set screw with dog point DIN 915 Steel Plain 45H M12X35

Numero articolo	07820.120.035
Marchio	-
UBB	951351678804
UNSPSC	31161518
EAN	8715492161628
PKG. di 100	Solo full box

Parametri tecnici:

Diametro	M12
Lunghezza	35 mm
Class	45H
Driving features	Hexagon socket
Material	Steel
Thread direction	Right
Point	Dog
Surface treatment	Plain
Thread	Metric thread

Info

These set screws are designed for pressure loads and are not suitable for tensile- or shear loads.


Standard

NEN	2344
NF	E27-182
BS	4168-4
ISO	4028
DIN	915
ASME	B18.3.6M

Specifica tecnica

d-D	M12
dp (max.)	8.5
L (mm)	35
P	1.75
s	6
t (min.)	4.8
z long (min.)	6
z long if L ≥	20

Disegno tecnico

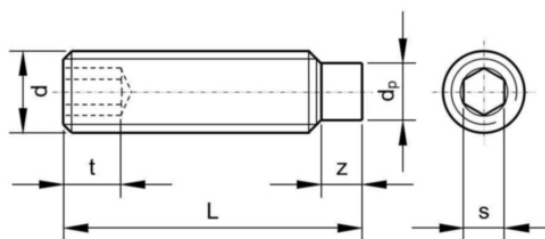

z short (min.) 3

FABORY