

Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.8 M12X140

Numero articolo	08250.120.140
Marchio	-
UBB	950351609777
UNSPSC	31161612
EAN	8715492555977
PKG. di 50	Solo full box

Parametri tecnici:

Diametro	M12
Lunghezza	140 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum.


Standard

NEN	≈303/697
DIN	603/555
ISO	≈8677/4034
NF	≈E27-351/E25-402
BS	≈4933/3692

Specifica tecnica

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
dk (max.)	30.65
k (max.)	6.95
L (mm)	140
m	10
P	1.75
fn (max.)	8.75
s	19

Disegno tecnico

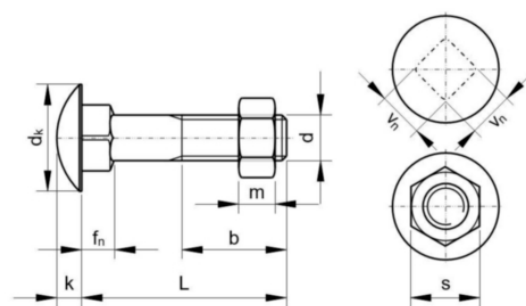

Vn (max.) 12.7

FABORY