

Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.8 M16X240

Numero articolo	08250.160.240
Marchio	-
UBB	950351612565
UNSPSC	31161612
EAN	8715492556516
PKG. di 10	Solo full box

Parametri tecnici:

Diametro	M16
Lunghezza	240 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	The property class of the corresponding nuts is 4 as a minimum.


Standard

DIN	603/555
ISO	≈8677/4034
NEN	≈303/697
BS	≈4933/3692
NF	≈E27-351/E25-402

Specifica tecnica

b (min.): 125mmL≤200mm	44
b (min.): L200mm	57
b (min.): L≤125mm	38
d-D	M16
dk (max.)	38.8
k (max.)	8.95
L (mm)	240
m	13
P	2
fn (max.)	12.9
s	24

Disegno tecnico

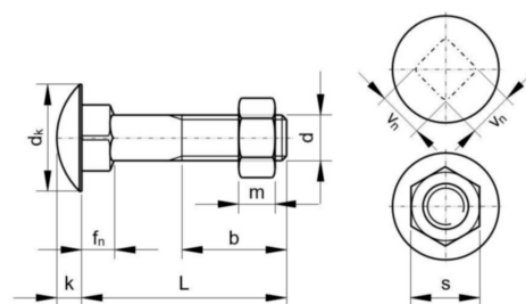

Vn (max.) 16.7

FABORY