


Spacer, 2 x internal thread Free-cutting steel Zinc plated M5X40X9

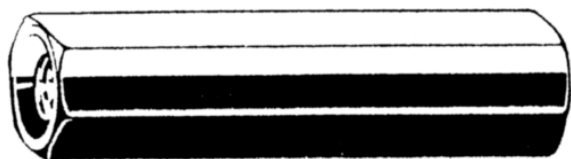

Numero articolo	11396.050.040
Marchio	-
UBB	950355642931
UNSPSC	31161816
EAN	8715492572073
PKG. di 100	Solo full box

Parametri tecnici:

Diametro	M5
Lunghezza	40 mm
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Tipo no.	H1200

Info When L = L#
the spacer has
a continuous
thread. Depending
on manufacturer
and availability parts
with slightly different
dimensions but with
equal functionality
may be supplied

Standard

Specifica tecnica

d-D	M5
L (mm)	40
L1	9
P	0.8
s	8

Disegno tecnico

