


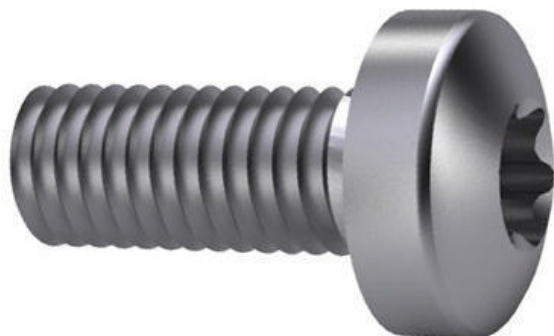

Hexalobular socket raised cheese head screw ISO 14583 Steel Zinc plated 8.8 M4X20

Numero articolo 24422.040.020

Marchio -

UBB 950353882554

UNSPSC 31161504

EAN 8715492627926

PKG. di 200 Solo full box

Parametri tecnici:

Diametro	M4
Lunghezza	20 mm
Class	8.8
Driving features	Hexalobular
Head shape	Raised cheese head
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread
Info	N = Max. recom. static load (centr. tension) [kN].

Standard

ISO 14583

Specifica tecnica

d-D	M4
Thread length (min.)	38
dk (max.)	8
Full thread if L ≤	40
k (max.)	3.1
L (mm)	20
P	0.7
Socket	20

Disegno tecnico

