


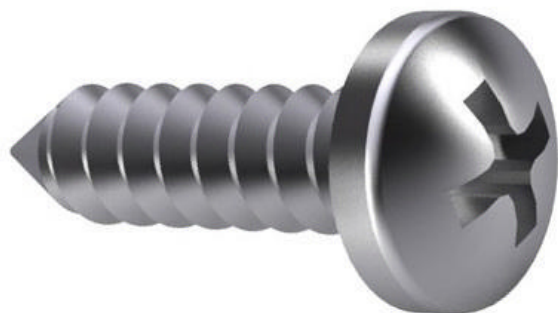

Cross recessed pan head tapping screw Phillips DIN 7981 C-H Steel Nickel plated ST3,5X19MM

Numero articolo 26200.035.019

Marchio -

UBB 950352065318

UNSPSC 31161507

EAN 8715492652898

PKG. di 200 Solo full box

Parametri tecnici:

Diametro	3.5 mm
Lunghezza	19 mm
Driving features	Phillips
Head shape	Pan head
Material	Steel
Surface treatment	Nickel plated
Thread	Self tapping thread

Info

Warning:
electroplating of
these products may
cause hydrogen
embrittlement.

Standard

DIN	7981 CH
NF	E25-658
ISO	7049 CH
ASME	B18.6.4

Specifica tecnica

D (mm)	3.5
dk	6.9
k	2.6
L (mm)	19
No. cross recess	2
P	1.3

Disegno tecnico

