


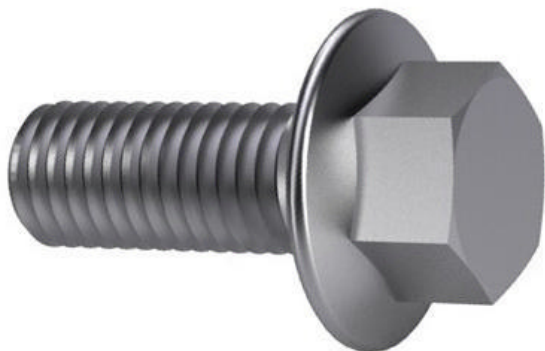

Hexagon flange bolt, fully threaded DIN ≈6921 Stainless steel A4 70 M10X50

Numero articolo	55018.100.050
Marchio	-
UBB	500634448012
UNSPSC	31161620
EAN	8715494554848
PKG. di 100	Solo full box

Parametri tecnici:

Diametro	M10
Lunghezza	50 mm
Class	70
Driving features	Hexagon
Head shape	Hexagon head
Material	Stainless steel
Material technical	A4
Thread direction	Right
Thread	Metric thread

Standard

ASME	≈B18.2.3.4M
DIN	≈6921
EN	≈1665
ISO	≈4162

Specifica tecnica

b (min.)	26
d-D	M10
dc (max.)	22.3
k (max.)	9.2
L (mm)	50
P	1.5
s	15

Disegno tecnico

