


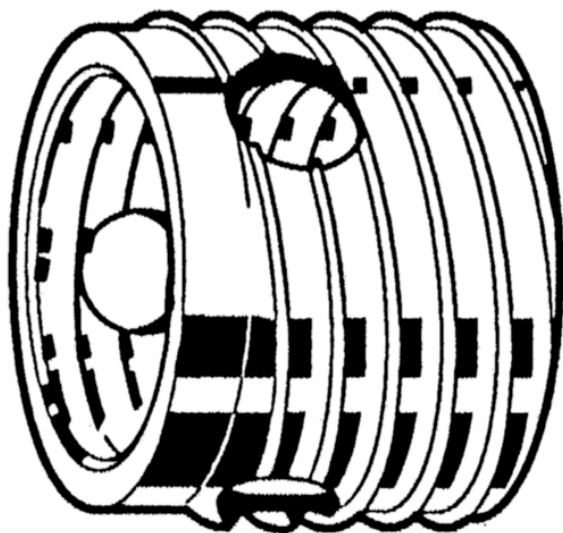

Self-cutting threaded insert type 307/308 Steel Zinc plated 307 M12X12

Numero articolo	71752.120.012
Marchio	-
UBB	500693875584
UNSPSC	31162802
EAN	8717077789708
PKG. di 1	Solo full box

Parametri tecnici:

Lunghezza	12 mm
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread
Tipo no.	307
Info	Drill depth (min.) = Minimum borehole depth for blind holes.307

Standard

Specifica tecnica

d1	M12
d2	16
Drill depth (min.)	15
L (mm)	12
P (d1)	1.75
P (d2)	1.75

Disegno tecnico

