


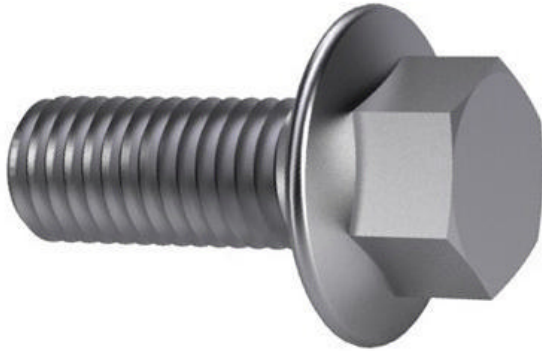

Zeskantflensbout DIN 6921 Staal Elektrolytisch verzinkt 10.9 M10X40

Artikelnummer	04137.100.040
Merk	-
UBB	500648944832
UNSPSC	31161620
EAN	8717077238619
PKG. van 100	Alleen volledige verpakkingen

Technische parameters

Diameter	M10
Lengte	40 mm
Klasse	10.9
Aandraaivoorziening	Zeskant
Kopsoort	Zeskantkop
Materiaalsoort	Staal
Draadrichting	Rechts
Oppervlaktebedekking	Elektrolytisch verzinkt
Draadsoort	Metrische schroefdraad

Standaarden

ASME	≈B18.2.3.4M
DIN	6921
EN	≈1665
ISO	≈4162

Info

Waarschuwing: bij het elektrolytisch behandelen van deze producten bestaat er gevaar voor het optreden van waterstofbrosheid. Specific features of hexagon bolts with flange: The flange enables built up forces under the bolt head to be spread over a larger area, consequently resulting in lower surface

pressure. Large
(oversized) holes
and/or tooling holes
can be covered by
the flange. Washers
are not necessary.

Technische specificatie

b (min.)	26
d-D	M10
dc(max.)	22.3
k (max.)	9.2
L (mm)	40
P	1.5
s	15

Technische tekening

