


Studbolt met 2 zeskantmoeren ASME B16.5/ B18.2.2 Roestvaststaal (RVS) ASTM A193 - ASTM A194 Gr.B8 - Gr.8 1 Inch X385 (15.1/4)

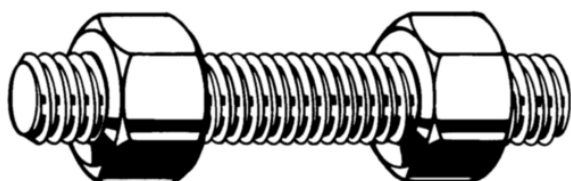

Artikel nummer	22534.254.387
Merk	-
UBB	500579002063
UNSPSC	31161619
EAN	8715494393195
PKG. van 1	Alleen volledige verpakkingen

Technische parameters

Diameter (Inch)	1 Inch
Length (L)	385
Length (inch)	15.1/4

Remarks
 Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Standaarden

ASTM	A193/A194
BS	≈4882
ASME	B16.5/B18.2.2

Klasse	Gr.B8 - Gr.8
Materiaalsoort	Roestvaststaal (RVS)
Materiaalsoort Technisch	ASTM A193 - ASTM A194
Draadrichting	Rechts
Draadsoort	Unified National Coarse

Technische specificatie

FARORV

B	1.5/8
Gangen per Inch	8
M	25

Technische tekening

