


**Studbolt met 2
 zeskantmoeren ASME B16.5/
 B18.2.2 Roestvaststaal (RVS)
 ASTM A193 - ASTM A194
 Rechts Gr.B8 - Gr.8 1 Inch
 X440 (17.1/4)**

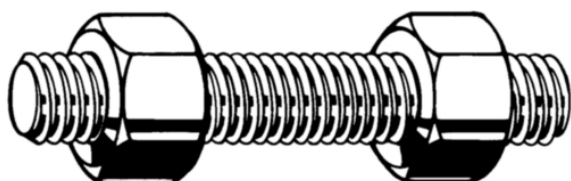

Artikel nummer	22534.254.438
Merk	-
UBB	500579003137
UNSPSC	31161619
EAN	8715494393300
PKG. van 1	Alleen volledige verpakkingen

Technische parameters

Diameter (Inch)	1 Inch
Lengte (L)	440
Lengte (inch)	17.1/4

Remarks Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Klasse	Gr.B8 - Gr.8
Materiaalsoort	Roestvaststaal (RVS)
Materiaalsoort Technisch	ASTM A193 - ASTM A194
Draadrichting	Rechts

Standaarden

ASME	B16.5 / B18.2.2
BS	4882
ASTM	A193/A194

Technische specificatie

B	1.5/8
---	-------

Technische tekening

M 25

Gangen per Inch 8

UR COURSE.
SETTING THE STANDARD
IN FASTENING SOLUTIONS

