


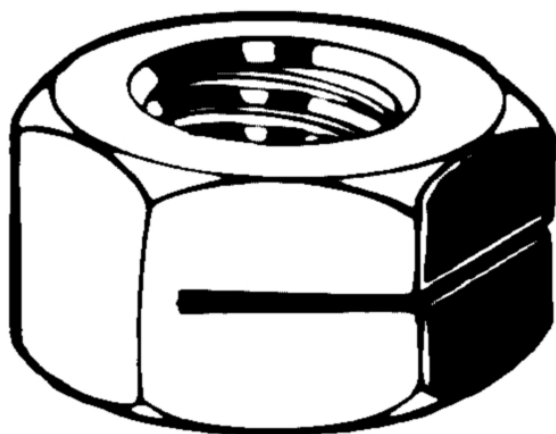

Zelfborgende zeskantmoer type H100-ESN Aluminium Geanodiseerd P60 M8

Artikelnummer	45300.080.001
Merk	-
UBB	950355189768
UNSPSC	31161727
EAN	8715492837592
PKG. van 200	Alleen volledige verpakkingen

Technische parameters

Diameter	M8
Klasse	P60
Aandraaivoorziening	Zeskant
Materiaalsoort	Aluminium
Draadrichting	Rechts
Oppervlaktebedekking	Geanodiseerd
Draadsoort	Metrische schroefdraad

Info

Kleurloos geanodiseerd. The self-locking function of the nut is realized by the elastic, axial displacement of the partly separated and compressed parts of the nut in relation to each other. The nut runs freely on the bolt until the groove is reached. With further rotation the clamping force on the thread flanks is achieved by the elastic reaction of the material, independant of the torque. Special

Standaarden

features of prevailing torque type H100-ESN hexagon nuts: Reversible – the locking slot is placed in the middle of the nut. Re-useable up to 5 times without significant performance loss. Resistant to shocks, vibrations and dynamic loads. Suitable for automatic assembly.

Technische specificatie

d-D	M8
m	8
P	1.25
s	13

Technische tekening

