


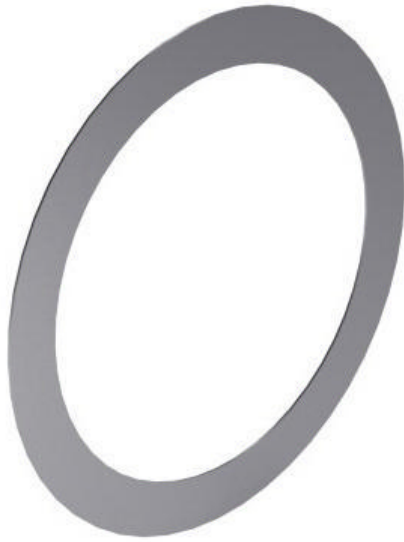

**Pasring (shim) dikte
h=0,1MM DIN 988
Roestvaststaal (RVS) A2
h=0,1mm 22X30MM**

Artikelnummer	51552.220.030
Merk	-
UBB	500700887655
UNSPSC	31163301
EAN	8715492965912
PKG. van 100	Alleen volledige verpakkingen

Technische parameters

Diameter	22 mm
Materiaalsoort	Roestvaststaal
Materiaalsoort Technisch	A2
Buitendiameter	30
Info	h=0,1mm

Standaarden

DIN	988
-----	-----

Technische specificatie

d1	22
d1(max.)	22.275
d1(min.)	22.065
d2	30
d2(max.)	29.935
d2(min.)	29.725
D (mm)	22
Dikte	0.1

Technische tekening

