


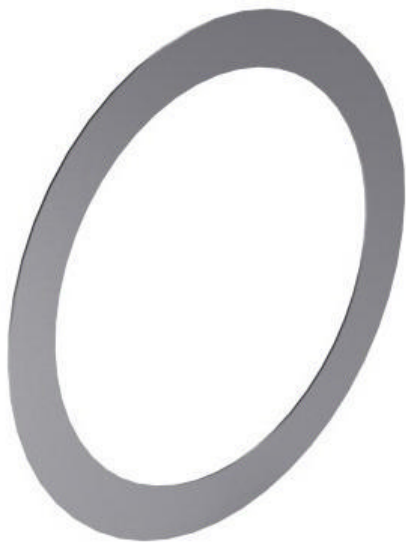

**Pasring (shim) dikte
h=0,2MM DIN 988
Roestvaststaal (RVS) A2
h=0,2MM 3X6MM**

Artikelnummer	51554.030.006
Merk	-
UBB	500700888315
UNSPSC	31163301
EAN	8715492965998
PKG. van 200	Alleen volledige verpakkingen

Technische parameters

Diameter	3 mm
Materiaalsoort	Roestvaststaal
Materiaalsoort Technisch	A2
Buitendiameter	6
Info	h=0,2MM

Standaarden

DIN	988
-----	-----

Technische specificatie

d1	3
d1(max.)	3.12
d1(min.)	3.02
d2	6
d2(max.)	5.97
d2(min.)	5.85
D (mm)	3
Dikte	0.2

Technische tekening

