


## Slotbout met zeskantmoer DIN 603/555 Staal Rechts Elektrolytisch verzinkt $\geq 4.6$ M16X130

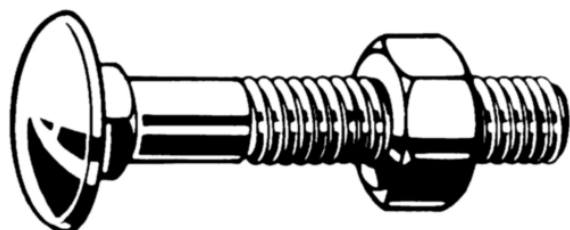

Artikel nummer	08250.160.130
Merk	-
UBB	950351611997
UNSPSC	31161612
EAN	8715492556431
PKG. van 25	Alleen volledige verpakkingen

### Technische parameters

Diameter (d-D)	M16
Klasse	$\geq 4.6$
Oppervlaktebedekking	Elektrolytisch verzinkt
Thread (long)	Metrische schroefdraad

### Standaarden

NF	- / E25-402
ASME	B18.5.2.3M/-
DIN	603/555
NEN	303/697
BS	4933/-

### Technische specificatie

b (min.): $L > 200\text{mm}$	57
Vn (max.)	16.7
k (max.)	8.95
b (min.): $125\text{mm} < L \leq 200\text{mm}$	44
fn (max.)	12.9
$d_k$ (max.)	38.8
P	2
b (min.): $L \leq 125\text{mm}$	38
s	24
m	13

### Technische tekening

