


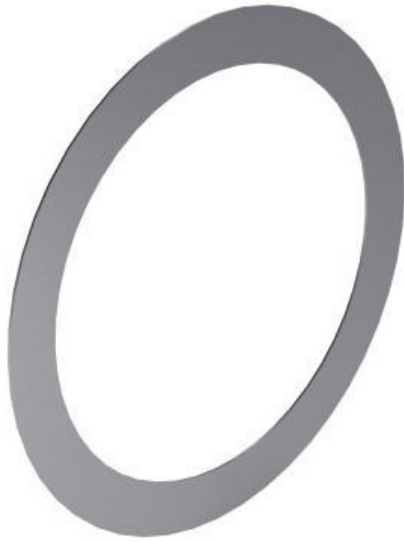

**Pasring (shim) dikte
h=1,0MM DIN 988 Staal 2
K 50 vlgs DIN 1624 Blank
h=1,0mm 26X37MM**

Artikelnummer	38590.260.037
Merk	-
UBB	950356317798
UNSPSC	31163301
EAN	8715492780881
PKG. van 50	Alleen volledige verpakkingen

Technische parameters

Diameter	26 mm
Materiaalsoort	Staal
Materiaalsoort Technisch	2 K 50 vlgs DIN 1624
Buitendiameter	37
Oppervlaktebedekking	Blank
Info	h=1,0MM

Standaarden

DIN	988
-----	-----

Technische specificatie

d1	26
d1(max.)	26.275
d1(min.)	26.065
d2	37
d2(max.)	36.92
d2(min.)	36.67
D (mm)	26
Dikte	1

Technische tekening

