


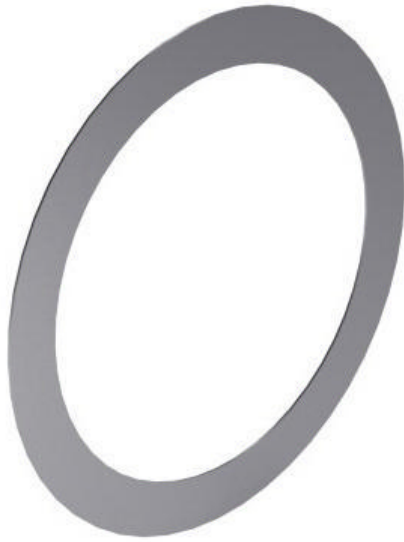

Pasring (shim) dikte h=0,25MM DIN 988 Staal 2 K 50 vlgs DIN 1624 Blank h=0,25mm 14X20MM

Artikelnummer	38602.140.020
Merk	-
UBB	500645302513
UNSPSC	31163301
EAN	8717077086999
PKG. van 100	Alleen volledige verpakkingen

Technische parameters

Diameter	14 mm
Materiaalsoort	Staal
Materiaalsoort Technisch	2 K 50 vlgs DIN 1624
Buitendiameter	20
Oppervlaktebedekking	Blank
Info	h=0,25MM

Standaarden

DIN	988
-----	-----

Technische specificatie

d1	14
d1(max.)	14.23
d1(min.)	14.05
d2	20
d2(max.)	19.935
d2(min.)	19.725
D (mm)	14
Dikte	0.25

Technische tekening

