


#urub cu cap hexagonal par#ial filetat DIN 931 O#el Zincat 8.8 M10X130/S=17

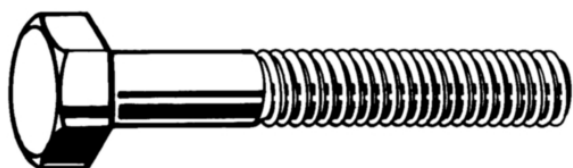

Numar art.	01200.100.130
Marcă	-
UBB	950351147273
UNSPSC	31161620
EAN	8715492025722
PKG. of 50	Exclusiv împachetare

Parametri tehnici

Diametru (d-D)	M10
Lungime (L) (mm)	130
Clasă	8.8
Tip antrenare	Hexagonal
Forma de cap	Cap hexagonal
Material (lung)	O#el
Direc#ie filet	Dreapta
Tratament al suprafe#ei	Zincat
Filete	Filet metric
Lă#ime de cheie	17

Standarde

NEN	1555
ASME	B18.2.3.1M
DIN	931
NF	E25-112
ISO	4014

Specificatii tehnice

P	1.50
b (min.): 125mm<L≤200mm	32
k	6.4
b (min.): L≤125mm	26
b (min.): L>200mm	45
s	17

Desen tehnic

