


#urub cu cap hexagonal par#ial filetat ISO 4014 O#el Zincat, pasivat galben 8.8 M20X100

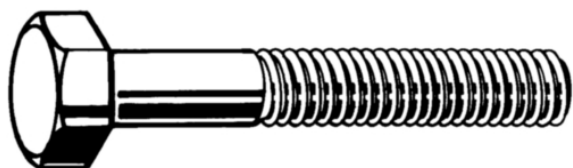

Numar art.	01220.200.100
Marcă	-
UBB	950351171919
UNSPSC	31161620
EAN	8715492034588
PKG. of 25	Exclusiv împachetare

Parametri tehnici

Diametru (d-D)	M20
Lungime (L) (mm)	100
Clasă	8.8
Tip antrenare	Hexagonal
Forma de cap	Cap hexagonal
Material (lung)	O#el
Direc#ie filet	Dreapta
Tratament al suprafe#ei	Zincat, pasivat galben
Filete	Filet metric

Standarde

NEN	1555
DIN	931
NF	E25-112
ASME	B18.2.3.1M
ISO	4014

Specificatii tehnice

b (min.): L>200mm	65
b (min.): L≤125mm	46
b (min.): 125mm<L≤200mm	52
P	2.50
s	30
k	12.5

Desen tehnic

