


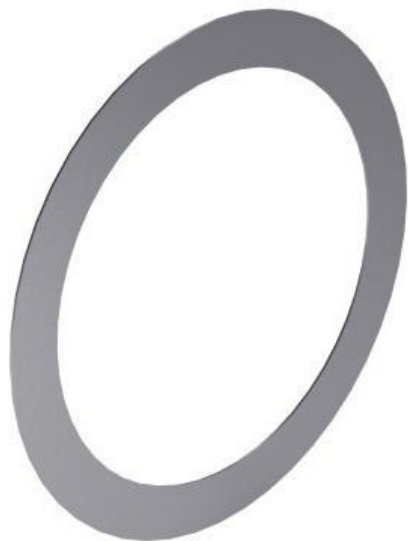

**Șaibe de reglare toleranțe,
grosime h=0,2MM DIN 988
Oțel inoxidabil A2 h=0,2MM
50X62MM**

Cod Articol	51554.500.062
Marcă	-
UBB	500700889222
UNSPSC	31163301
EAN	8715492966285
PKG. of 100	Exclusiv împachetare

Parametri tehnici

Diameter	50 mm
Material	Oțel inoxidabil
Material tehnic	A2
Diametru extern	62
Info	h=0,2MM

Standarde

DIN	988
-----	-----

Specificatii tehnice

d1	50
d1 (max.)	50.33
d1 (min.)	50.08
d2	62
d2 (max.)	61.9
d2 (min.)	61.6
D (mm)	50
Grosime	0.2

Desen tehnic

