


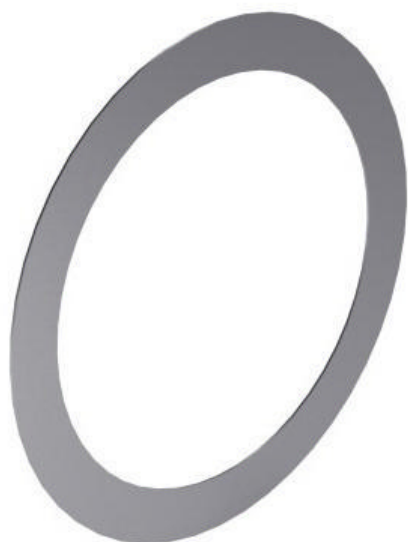

**Șaibe de reglare toleranțe,  
grosime h=0,5MM DIN 988  
Oțel inoxidabil A2 h=0,5MM  
8X12MM**

|             |                      |
|-------------|----------------------|
| Cod Articol | 51555.080.012        |
| Marcă       | -                    |
| UBB         | 500700889552         |
| UNSPSC      | 31163301             |
| EAN         | 8715492966353        |
| PKG. of 200 | Exclusiv împachetare |

## Parametri tehnici

|                 |                 |
|-----------------|-----------------|
| Diameter        | 8 mm            |
| Material        | Oțel inoxidabil |
| Material tehnic | A2              |
| Diametru extern | 12              |
| Info            | h=0,5MM         |

## Standarde

|     |     |
|-----|-----|
| DIN | 988 |
|-----|-----|

## Specificatii tehnice

|           |       |
|-----------|-------|
| d1        | 8     |
| d1 (max.) | 8.19  |
| d1 (min.) | 8.04  |
| d2        | 12    |
| d2 (max.) | 11.95 |
| d2 (min.) | 11.77 |
| D (mm)    | 8     |
| Grosime   | 0.5   |

## Desen tehnic

