


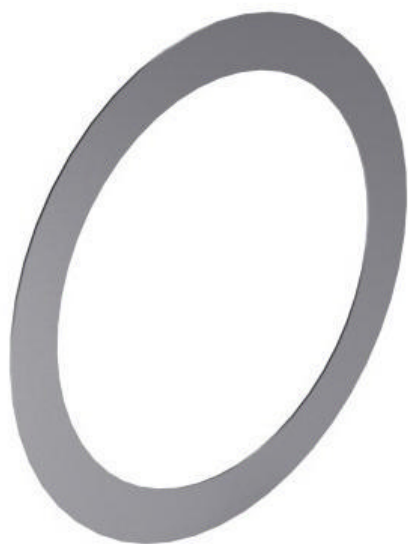

**Șaibe de reglare toleranțe,
grosime h=0,3MM DIN 988
Oțel inoxidabil A2 h=0,3MM
18X25MM**

Cod Articol	51556.180.025
Marcă	-
UBB	500700891285
UNSPSC	31163301
EAN	8715492966636
PKG. of 100	Exclusiv împachetare

Parametri tehnici

Diameter	18 mm
Material	Oțel inoxidabil
Material tehnic	A2
Diametru extern	25
Info	h=0,3MM

Standarde

DIN	988
-----	-----

Specificatii tehnice

d1	18
d1 (max.)	18.23
d1 (min.)	18.05
d2	25
d2 (max.)	24.935
d2 (min.)	24.725
D (mm)	18
Grosime	0.3

Desen tehnic

