


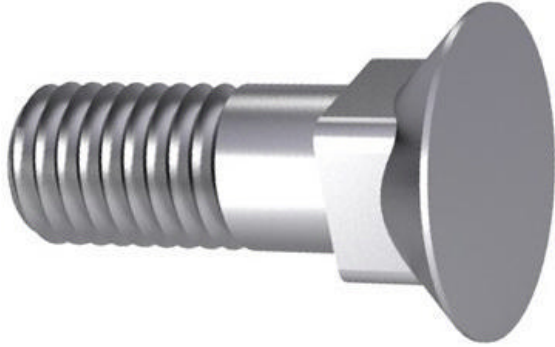

Flat countersunk square neck bolt with short square neck DIN ≈608 Steel Plain 8.8 M12X45

Article number	01036.120.045
Brand	-
UBB	500644987314
UNSPSC	31161612
EAN	8717077048386
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M12
Length	45 mm
Class	8.8
Head shape	Countersunk head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

DIN	≈608
-----	------

Technical Specification

b (min.)	30
d-D	M12
dk (max.)	24.65
L (mm)	45
P	1.75
fn (max.)	11.05
v (max.)	12.7

Technical Drawing

