


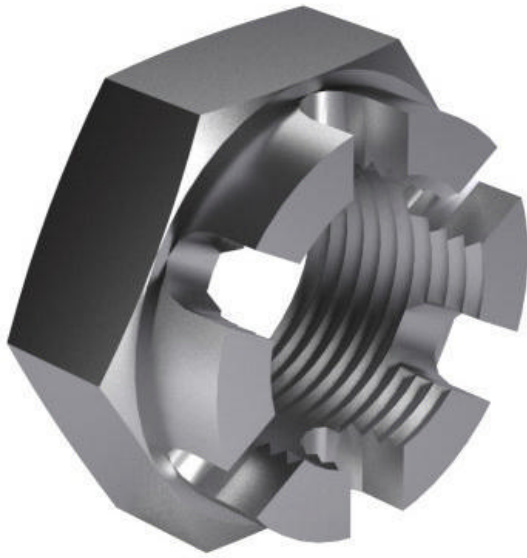

## Hexagon thin slotted and castle nut (old type) DIN 937 Steel Plain 17H M10

|                |               |
|----------------|---------------|
| Article number | 01605.100.001 |
| Brand          | -             |
| UBB            | 500648123452  |
| UNSPSC         | 31161707      |
| EAN            | 8717077206267 |
| PKG. of 1      | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Diameter          | M10           |
| Class             | 17H           |
| Driving features  | Hexagon       |
| Material          | Steel         |
| Thread direction  | Right         |
| Surface treatment | Plain         |
| Thread            | Metric thread |

### Standards

|     |     |
|-----|-----|
| DIN | 937 |
|-----|-----|

### Technical Specification

|                  |     |
|------------------|-----|
| d-D              | M10 |
| m                | 8   |
| n                | 2.8 |
| P                | 1.5 |
| s                | 17  |
| Split pin DIN 94 | 2.5 |

### Technical Drawing

