

Hexagon head bolt DIN 931 Steel Zinc plated yellow passivated 10.9 M12X60/ S=19

Article number	04104.120.060
Brand	-
UBB	953351909064
UNSPSC	31161620
EAN	8715493175440
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M12
Length	60 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated yellow passivated
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.


Standards

NF	E25-112
NEN	1555
DIN	931
ASME	B18.2.3.1M
ISO	4014

Technical Specification

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
k	7.5
L (mm)	60

Technical Drawing

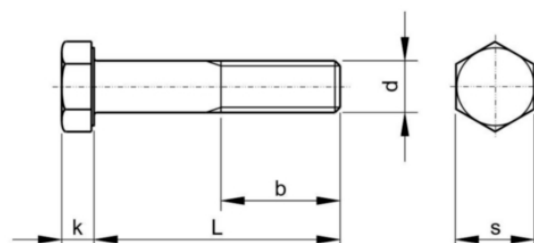

P

1.75

S

19

FABORY