


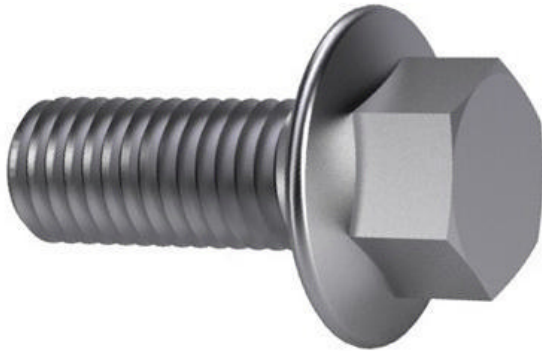

Hexagon flange bolt EN 1665 Steel Zinc plated 10.9 M10X16

Article number	04140.100.016
Brand	-
UBB	500650800823
UNSPSC	31162400
EAN	8717077294530
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M10
Length	16 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.

Standards

DIN	≈6921
ISO	≈4162
ASME	≈B18.2.3.4M
EN	1665

Technical Specification

b (min.)	26
d-D	M10
dc (max.)	22.3
k (max.)	10.4
L (mm)	16
P	1.5
s	16

Technical Drawing

