


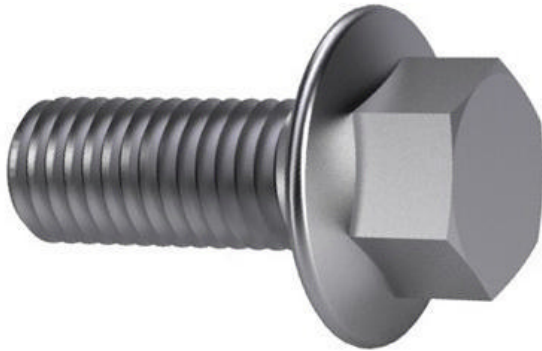

Hexagon flange bolt EN 1665 Steel Zinc plated 10.9 M10X25

Article number	04140.100.025
Brand	-
UBB	500650801086
UNSPSC	31162400
EAN	8717077294554
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M10
Length	25 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.

Standards

ISO	≈4162
DIN	≈6921
ASME	≈B18.2.3.4M
EN	1665

Technical Specification

b (min.)	26
d-D	M10
dc (max.)	22.3
k (max.)	10.4
L (mm)	25
P	1.5
s	16

Technical Drawing

