

Hexagon head bolt with hexagon nut DIN 601/555 Steel Zinc plated 4.8 M24X70

Article number	08200.240.070
Brand	-
UBB	950351103110
UNSPSC	31161620
EAN	8715492552761
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M24
Length	70 mm
Class	4.6
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

ISO	≈4016/4033
NF	E25-115-1/E25-402
NEN	102/697
DIN	601/555

Technical Specification

b (min.): 125mm $L \leq 200$ mm	60
b (min.): $L > 200$ mm	73
b (min.): $L \leq 125$ mm	54
d-D	M24
k	15
L (mm)	70
m	19

Technical Drawing

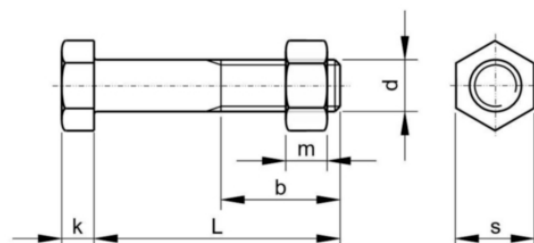

P

3

s

36