

Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.8 M6X90

Article number	08250.060.090
Brand	-
UBB	950351602095
UNSPSC	31161612
EAN	8715492554987
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M6
Length	90 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

ISO	≈8677/4034
DIN	603/555
NEN	≈303/697
NF	≈E27-351/E25-402
BS	≈4933/3692

Technical Specification

b (min.): 125mmL≤200mm	24
b (min.): L≤125mm	18
d-D	M6
dk (max.)	16.55
k (max.)	3.88
L (mm)	90
m	5
P	1
fn (max.)	4.6

Technical Drawing

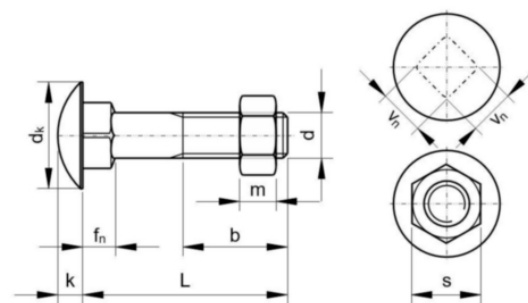

s

10

Vn (max.)

6.48

