

Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.8 M8X90

Article number	08250.080.090
Brand	-
UBB	950351603812
UNSPSC	31161612
EAN	8715492555328
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M8
Length	90 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info	The property class of the corresponding nuts is 4 as a minimum. Depending the supplier material class can differ (4.6 or 4.8)
------	---


Standards

DIN	603/555
ISO	≈8677/4034
NF	≈E27-351/E25-402
BS	≈4933/3692
NEN	≈303/697

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	90
m	6.5
P	1.25

Technical Drawing

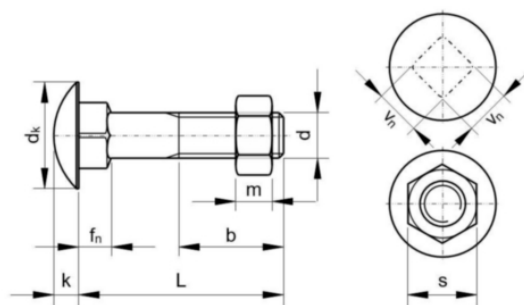

fn (max.) 5.6

s 13

Vn (max.) 8.58