

Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.8 M10X160

Article number	08250.100.160
Brand	-
UBB	950351606880
UNSPSC	31161612
EAN	8715492555632
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M10
Length	160 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info	The property class of the corresponding nuts is 4 as a minimum. Depending the supplier material class can differ (4.6 or 4.8)
------	---


Standards

DIN	603/555
BS	≈4933/3692
NEN	≈303/697
NF	≈E27-351/E25-402
ISO	≈8677/4034

Technical Specification

b (min.): 125mmL≤200mm	32
b (min.): L200mm	45
b (min.): L≤125mm	26
d-D	M10
dk (max.)	24.65
k (max.)	5.38
L (mm)	160
m	8
P	1.5

Technical Drawing

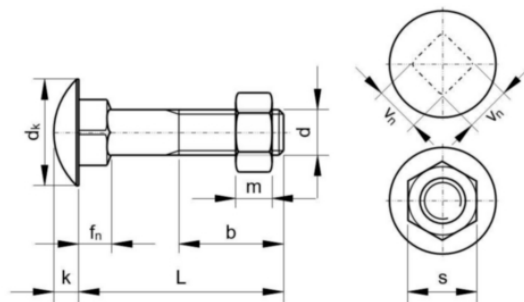

fn (max.) 6.6

s 17

Vn (max.) 10.58