

Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.8 M12X120

Article number	08250.120.120
Brand	-
UBB	950351609512
UNSPSC	31161612
EAN	8715492555953
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M12
Length	120 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	The property class of the corresponding nuts is 4 as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NEN	≈303/697
DIN	603/555
NF	≈E27-351/E25-402
ISO	≈8677/4034
BS	≈4933/3692

Technical Specification

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
dk (max.)	30.65
k (max.)	6.95
L (mm)	120
m	10
P	1.75

Technical Drawing

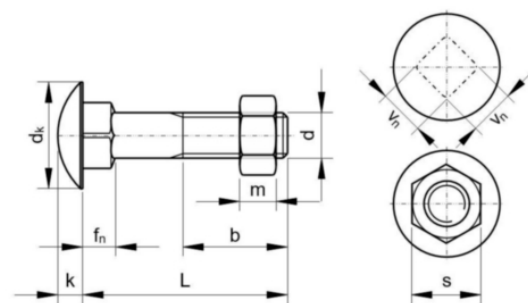

fn (max.) 8.75

s 19

Vn (max.) 12.7