


Spacer, 2 x internal thread Free-cutting steel Zinc plated M3X20X7

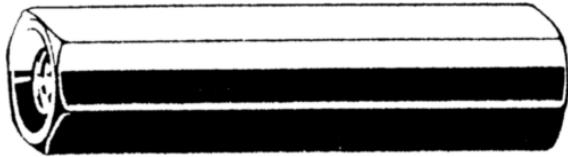

Article number	11396.030.020
Brand	-
UBB	950355641453
UNSPSC	31161816
EAN	8715492571861
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M3
Length	20 mm
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	H1200
Info	When L = L# the spacer has a continuous thread. Depending on manufacturer and availability parts with slightly different dimensions but with equal functionality may be supplied

Standards

Technical Specification

d-D	M3
L (mm)	20
L1	7
P	0.5
s	5.5

Technical Drawing

