


Spacer, internal and external thread Free-cutting steel Zinc plated M5X20X11

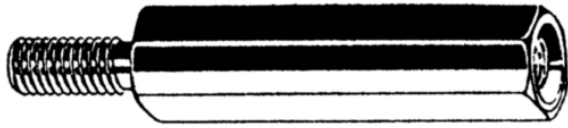

Article number	11398.050.020
Brand	-
UBB	950355644598
UNSPSC	31161816
EAN	8715492572400
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M5
Length	20 mm
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	H1202
Info	Depending on manufacturer and availability parts with slightly different dimensions but with equal functionality may be supplied

Standards

Technical Specification

d-D	M5
L (mm)	20
L1	10
L2	11
P	0.8
s	8

Technical Drawing

