

Self-clinching blind stand off Steel Zinc plated M3X4,18X25X9,5

Article number	14421.030.025
Brand	-
UBB	500656714689
UNSPSC	31161816
EAN	8712423015708
PKG. of 1	Full Box Only

Technical Parameters


Diameter	M3
Length	25 mm
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	Steel self-clinching blind stand offs are suitable for use in steel sheet with a maximum hardness of HRB70. For steel sheets with higher hardnesses, rivet bushes are recommended.

Standards

Technical Specification

B (min.)	9.5
C	4.18
d-D	M3
Hole size	4.2
L (mm)	25
Min. distance sheet edge	6

Technical Drawing

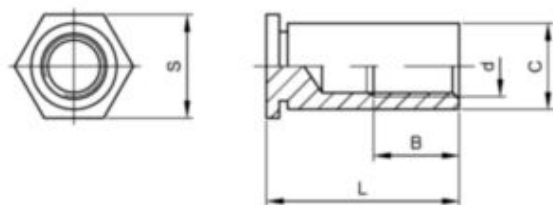

Min. recommended sheet thickness 1

S  4.8