


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Plain Gr.B7 - Gr.2H 1/2X120 (4.3/4)

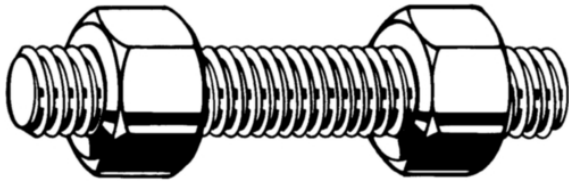

Article number	22080.127.120
Brand	-
UBB	950353436237
UNSPSC	31161619
EAN	8715492617002
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	1/2
Length (L) (mm)	120
Length (L) (Inch - ft)	4.3/4

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B7 - Gr.2H
Material	Steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Surface treatment	Plain
Thread	Unified National Coarse

Standards

ASTM	A193/A194
ASME	B16.5/B18.2.2
BS	≈4882

Technical Specification

B	7/8
---	-----

Technical Drawing

M 12.3
Threads per inch 13

