


## Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Plain Gr.B7 - Gr.2H 3/4X105 (4.1/8)

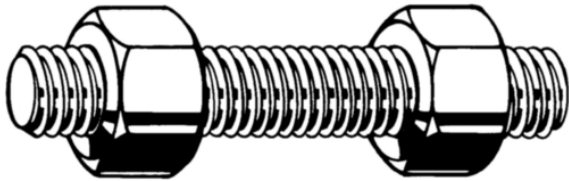

Article number	22080.191.105
Brand	-
UBB	500578018912
UNSPSC	31161619
EAN	8715494337939
PKG. of 1	Full Box Only

### Technical Parameters

Diameter (inch)	3/4
Length (L) (mm)	105
Length (L) (Inch - ft)	4.1/8

**Info**

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B7 - Gr.2H
Material	Steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Surface treatment	Plain
Thread	Unified National Coarse

### Standards

BS	≈4882
ASME	B16.5/B18.2.2
ASTM	A193/A194

### Technical Specification

B	1.1/4
---	-------

### Technical Drawing

M 18.7  
Threads per inch 10

